

Hand switch


EHA 1

Benefits

- Robust ergonomic design
- Tactile buttons, clearly marked
- Easy mountable fastening hook




Suitable pillars, actuators and control units

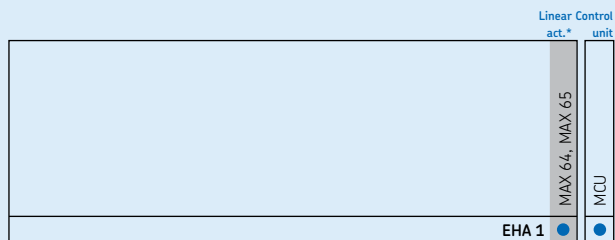

* With integrated control units

Dimensional drawing

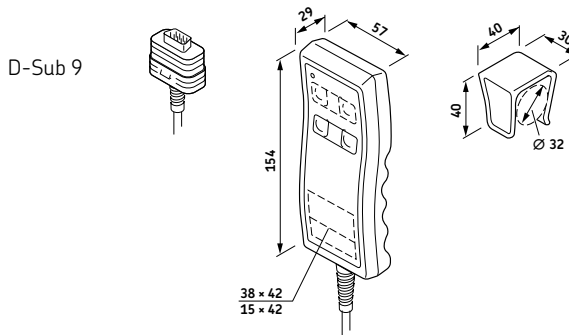


Technical data

	Unit	EHA 1
Max. operating channels	n°	2
Operating power	V DC/mA	12/50
Type of protection	IP	67
Color	–	Grey

Accessories

	Designation	Order N°
Hook with sticker	ZBG-145361-000	M/0125538

 Ordering key



Type

Number of channels:

- 1 channel
- 2 channels

1
2

Hook:

- Yes mounted with hook
- Hook supplied separately

1
2

Cable / connecting plug:

- Coiled, 1,3 m/2,5 m / D-sub 9-pin plug
- Coiled 2,5 m/3,5 m / D-sub 9-pin plug

B
F

Symbols:

- None
- 1 channel: Arrow up/down
Head
- 2 channels: Arrow up/down
Head/foot
Level/head

00
10
11
20
22
23

