


## R14

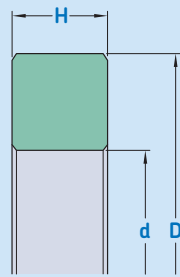

Ordering dimensions in **blue**

**Standard dimensions**

Because of the design diversity of this profile, it is not useful to list standard dimensions.

The size and position of the tolerance field have to be considered and may be adapted to special functions.

**Ordering example**

Profile  
d x D x H [mm]  
Sealing material

Rotary seal R14  
85 x 100 x 2  
SKF Ecotal

## Operating parameters

Material Seal	Temperature	
	from	to
–	°C	
■ ECOPUR	–30	
■ ECOPUR LD	–35	
■ G-ECOPUR	–30	
■ G-ECOPUR 54 D	–20	
■ H-ECOPUR	–20	+110
■ S-ECOPUR		
■ T-ECOPUR	–50	
■ X-ECOPUR	–30	
■ X-ECOPUR H		
■ X-ECOPUR S	–20	
■ SKF Ecorubber-H	–25	+150
■ SKF Ecorubber-1	–30	+100
■ SKF Ecorubber-2	–20	+200
■ SKF Ecorubber-3	–50	+150
■ SKF Ecosil	–60	+200
■ SKF Ecoflon 1		
■ SKF Ecoflon 2	–200	+260
■ SKF Ecoflon 3		
■ SKF Ecoflon 4		
■ SKF Ecomid	–40	+100
■ SKF Ecopaek	–100	+260
■ SKF Ecotal	–50	+100
■ SKF Ecowear 1000	–200	+90

IMPORTANT NOTE: Materials are depending on the application. Please contact SKF for more information.

[skf.com](http://skf.com) | [skf.com/seals](http://skf.com/seals)

© SKF, ECOPUR, G-ECOPUR, H-ECOPUR, S-ECOPUR, T-ECOPUR and X-ECOPUR are registered trademarks of the SKF Group.

© SKF Group 2015

The contents of this publication are the copyright of the publisher and may not be reproduced (even extracts) unless prior written permission is granted. Every care has been taken to ensure the accuracy of the information contained in this publication but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

PUB SE/P8 11886/1 · April 2015

**SKF**®