

CR Scotseal PlusXL

The CR Scotseal PlusXL is a unitized, one-piece hand installable design seal that offers maximum sealing life under virtually all operating conditions. This seal uses an advanced HNBR material that provides high temperature capability, great wear resistance, and broad compatibility with synthetic lubricants. The CR Scotseal PlusXL is the preferred choice among many OE truck and trailer manufacturers and is the OE standard seal in pre-assembled hubs, due to its proven history of high performance.



Hand installable

- Eliminates installation problems and avoids costly "do overs"
- Ends searching for the specific tool for each seal part number

Advanced sealing materials

- HNBR material provides great heat resistance in normal operating temperatures
- EPDM material on the ID makes a perfect seal even on worn spindles
- Provides longer life in contaminated conditions
- Compatible with all popular synthetic lubricants

Unitized design with 4 sealing lips

- Provides clean running surfaces for sealing lips
- Primary Waveseal sealing lip sweeps oil back on the bearings for cooler operation
- 3 dirt barriers keep out contaminants extending service life

Extended warranty coverage

- 3 years / 300,000 mile warranty *

* See TFO publication 457975 for details.

Installs quickly and correctly by hand — every time!

The CR Scotseal PlusXL requires two tools — your hands!

Just slightly lubricate the ID and OD of the new seal with the wheel end lubricant and press the new seal evenly into the hub. Wait 5 minutes and install the hub onto the spindle.



View detailed technical and product videos at www.skfpartsinfo.tv



Follow us on Twitter @skfpartsinfo to stay on top of all the latest technical and product information.

SKF VSM NA
890 N. State Street
Suite 200
Elgin, IL 60123
800-882-0008
www.vsm.skf.com


Designed to keep out road contamination and oil in at the bearings

HNBR OD

- Easy to install
- No tools required

Primary sealing lip

- Patented Waveseal sweeps oil back to the bearings
- Bearings and seal run cooler, extending wheel end life
- Provides great heat resistance and broad compatibility with synthetic lubricants

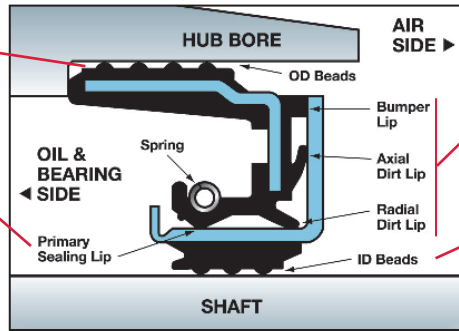

Bumper, axial and radial dirt lips

- 3 dirt barriers keep out contaminants
- Bumper lip acts as a primary dirt excluder
- Added bearing protection

EPDM ID

- Easy to install
- Perfect seal even on worn spindles
- Optimized sealing life under virtually all driving conditions

Popular applications

Applications	CR Scotseal PlusXL	Conventional				Pre-adjusted	
		Inner Cup	Inner Cone	Outer Cup	Outer Cone	Inner Bearings	Outer Bearings
Steer							
Steer Axle, 4,700 lb, 7,500 lb, 8,000 lb, Meritor, Navistar	28759	JM207010	JM207049-AVP	BR25820	BR25877	N/A	N/A
FF Steer Axle, 12,000 lb, Eaton, Ford, Freightliner, Kenworth, Meritor, Navistar, Peterbilt, Volvo, Western Star	35058	SET413 HM212011 VP HM212049 VP		SET406 BR3720 BR3782		SET427*	SET428*
FL Steer Axle, 16,000 lb, 20,000 lb, Ford, Freightliner, Kenworth, Mack, Meritor, Navistar, Peterbilt, Volvo, Western Star	43761	SET423 BR6420 6461-A VP		SET424 552-A VP 555-S VP		SET445*	SET446*
Drive							
Drive Axle, 34,000 lb, Eaton, Ford, Meritor, Navistar, Volvo	38776	SET411 BR47620 BR47686		SET408 BR39520 BR39590		N/A	N/A
Drive Axle, 34,000 lb, 36,000 lb, 38,000 lb, Mack	45093	SET401 BR572 BR580		SET425 BR563 BR567		SET430*	N/A
R Drive Axle, 38,000 lb, 46,000 lb, Eaton, Ford, Freightliner, Kenworth, Meritor, Navistar, Peterbilt, Volvo, Western Star	47691	SET403 592-A VP 594-A VP		SET401 BR572 BR580		SET445*	SET446*
Drive Axle, 40,000 lb, 44,000 lb, Mack	42673	SET421 HM516410 VP HM516449-A VP		SET426 BR47620 BR47679		N/A	N/A
Trailer							
Trailer Axle, 19,000 lb, Eaton, Meritor, Spicer, Standard Forge	40129	SET405 BR653 BR663		SET413 HM212011 VP HM212049 VP		N/A	SET427*
TN Trailer Axle, 22,500 lb, Eaton, Meritor, Spicer, Standard Forge	46300	SET414 HM218210 VP HM218248 VP		SET413 HM212011 VP HM212049 VP		SET431*	SET427*
TP Trailer Axle, Eaton P-22, Fruehauf, Meritor, Pro-Par, Spicer	42627	SET415 HM518410 VP HM518445 VP		SET415 HM518410 VP HM518445 VP		SET432*	SET432*

Part numbers listed are for reference only. Some applications may use parts not listed on this chart. See SKF catalog 457601 for complete application listings.

* Cup and Cone not sold separately.

Interchange

CR Scotseal PlusXL	Stemco Discover	Stemco Guardian	Stemco Voyager	FM Red 37	FM Gold 38	Meritor Standard	Meritor Premium	ConMet
28759	N/A	308-0866	383-0166	370150A	N/A	N/A	N/A	N/A
35058	383-0236	308-0836	383-0136	370001A	380001A	MER0136	MER0236	10045885
38776	393-0212	309-0912	393-0112	370023A	380023A	MER0112	MER0212	N/A
40129	373-0213	307-0713	373-0113	370036A	380036A	MER0113	MER0213	N/A
42627	373-0223	307-0723	373-0123	370065A	380065A	MER0123	MER0223	10045889
42673	393-0204	309-0904	393-0104	370031A	380031A	MER0104	MER0204	N/A
43761	383-0264	308-0864	383-0164	370048A	380048A	MER0164	MER0264	10045883
45093	393-0203	309-0903	393-0103	370022A	380022A	MER0103	MER0203	N/A
46300	373-0243	307-0743	373-0143	370025A	380025A	MER0143	MER0243	10045888
47691	393-0273	309-0973	393-0173	370003A	380003A	MER0173	MER0273	10045887

© SKF, Scotseal and Waveseal are registered trademarks of the SKF Group. © SKF Group 2018

The contents of this publication are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this publication but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.